


Manifold Block & Panels

Did you know?

Automated
Bottle Filling &
Recharging



Manifold
Block

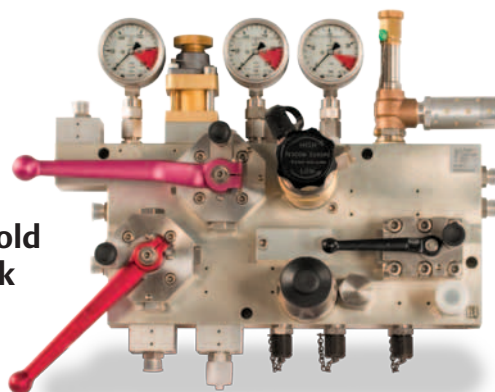

Fueling Panel



Stackable Pressure
Components

Changeover Panel



A system from TESCO can streamline your process!

TESCOM integrates different pressure control components into compact, efficient manifold blocks and panels. Our innovative designs reduce potential leak paths and allow for easy integration into your application. Increase your capacity and free up your internal resources by letting TESCO streamline your process.

A TESCO manifold block or panel will:

- Reduce leak paths to save loss of media and ensure safe connections
- Reduce the required number of fittings, saving space, reducing inventory and lowering cost
- Simplify disorganized layouts, making it easier to troubleshoot and perform preventative maintenance

From concept to commission, TESCO works closely with you to seamlessly integrate a streamlined system that meets your specific process or industry requirements.

See reverse for more information.

Standard Products & Custom Integrated Systems

for hydraulic & pneumatic applications

Standard Configurable Panels/Manifold Blocks



Closed Loop Electronic Control



Custom Manifold Blocks/Panels



Automated Test Stands



ENTRY

LEVEL OF INTEGRATION

ADVANCED

- Mechanical automation
- Reduced leak paths
- Reduced footprint
- Custom designed to application

- Electromechanical automation
- Software enabled
- High accuracy
- Eliminate droop
- Data acquisition

- Integrate third party components
- Eases preventative maintenance & troubleshooting
- Subsystem for larger projects
- Build to print or complete design & build

- Complete system hardware & software
- Networked or stand alone
- Safety interlocks & FMEA
- Factory Acceptance Test & documentation packages

Services provided by TESCOM include design & engineering, documentation and assembly/test. TESCOM offers Control Implementation (PC Solution, Controller Solution, Hardware Only) and Data Management (Data Storage & Test Reports).

Represented by:

Contact TESCOM:

Americas

USA
T +1 800 447 1250
+1 763 241 3238
F +1 763 241 3224
na.tescom@emerson.com
www.tescom.com

Europe

Germany
T +49 (0) 3 88 23/31-0
F +49 (0) 3 88 23/31-199
eu.tescom@emerson.com
www.tescom-europe.com

United Kingdom
T +44 1698 424254
F +44 1698 459299

uk.tescom@emerson.com
www.tescom-europe.co.uk

Asia Pacific

China
T +86 21 2892 9499
F +86 21 2892 9001

apc.tescom@emerson.com
www.tescom.com

Middle East & Africa

United Arab Emirates
T +971 4 811 8100 x8446
F +971 4 886 5465

mea.tescom@emerson.com
www.tescom.com

TESCOM

©TESCOM Corporation, 2009; All Rights Reserved.
TESCOM is a business unit of Emerson Process Management Regulator Technologies, Inc.
Trademarks are property of divisions of Emerson Process Management.

DFLYR1974X012 Rev. 9/09


EMERSON
Process Management