

7S Continuous Swivel 7P Portable Series

Available with or without handlamps

Furnished with 18-3 (2 wire plus safety ground) yellow SJOOW-A cord.

NEC/CEC:
Listed for Ordinary Locations

Applications

- A safe and convenient source of retractable power cord for:
 - Portable lighting
 - Power supply
 - General utility service

Features

- 7S and 7SV Series
 - Enclosed construction.
 - Furnished with 7.6 meters (25 feet) of yellow, extra flexible, 18-3 SJOOW-A cord (2-conductor plus safety ground).
 - High quality, double copper brushes.
 - Locking ratchet holds cord at desired length.
 - Adjustable ball stop controls return limit of retractable cord.
 - Hubs in all covers have integral bushings to protect conductor insulation from damage. Hub plate openings are smooth.
 - Continuous 360° patented swiveling action without power interruption or tangling of cord.
 - 7S Series offers choice of hand-lamps available as accessories.
 - 7SV Series includes NEMA 4X (enclosed and gasketed) handlamp to accommodate up to 100 Watt lamp, 6.1 meters (20 feet) of SJOOW-A cord.
 - Models available with built-in automatic switch which activates light when cord is pulled out.
 - Convenient flush type mounting ring fits 4" octagonal outlet box or fuse bracket.
 - Accessory bracket permits wall mounting.
 - Supplied with handlamp to accommodate up to 100 Watt lamp.

Standard Materials

- Reels: steel construction
- Cord: type SJOOW-A, yellow thermoset jacket, oil-resistant, 300 Vac rating

Standard Finishes


- Gray hammer epoxy/polyester powder coat

NEC/CEC Certifications and Compliances

- UL Listed: E4961
- UL Standard: 355
- CSA Listed: LR3060
- Meets OSHA requirements



7S Series

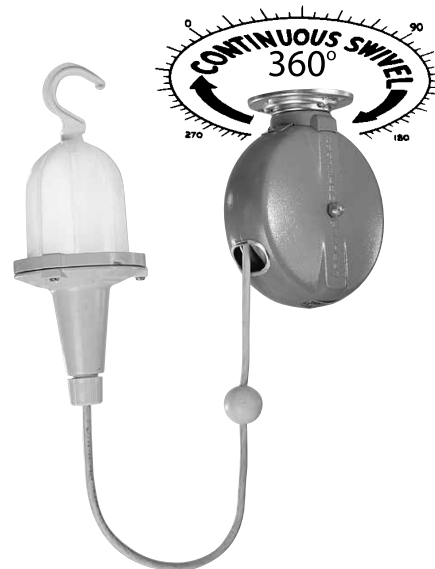


7SV Series

7S Continuous Swivel 7P Portable Series



Available with or without handlamps

Furnished with 18-3 (2 wire plus safety ground) yellow SJOOW-A cord.


NEC/CEC:
Listed for Ordinary Locations

	Description	Cord Length Meters (Feet)	Cord Size	Rating Amp/Voltage	Catalog Number
 <p>7SV Series</p>	7S continuous swivel, grounded Reelite™ Less handlamp. Max. accessory weight: 560 grams (20 oz). Handlamps ① available. Furnished with yellow SJOOW-A cord and RE-FB4 fuse bracket assembly.	7.6 (25)	18-3 SJOOW-A	4 Amp, 125 Vac	RE-7S2G
	7S Reelite™ with NEMA 4X, indoor use handlamp Continuous swivel, grounded Reelite™ complete with RE-VHL100N (enclosed and gasketed) handlamp ① as shown. Accommodates up to 100 Watt lamp. Furnished with yellow SJOOW-A cord.	6.1 (20)	18-3 SJOOW-A	4 Amp, 125 Vac	RE-7SV2G
	7S Reelite™ with NEMA 4X, indoor use handlamp and automatic switch Continuous swivel, grounded Reelite™ complete with automatic switch (not illustrated) and RE-VHL100N (enclosed and gasketed) handlamp ①. Accommodates up to 100 Watt lamp. Furnished with yellow SJOOW-A cord.	6.1 (20)	18-3 SJOOW-A	4 Amp, 125 Vac	RE-7SV2G-AS

Accessories

	Description	Catalog Number
	Ball Stop Yellow 2-piece split design permits installation without disconnecting handlamp or receptacle on end of cord. Made of polypropylene. Installs on SJOOW-A cord used on all Appleton portable reels.	RE-PBS-1
	Handlamps Handlamps are available as optional accessories. For ordering information refer to the <i>Lighting: Portable Lighting Section</i>	

Dimensions in Millimeters (Inches)

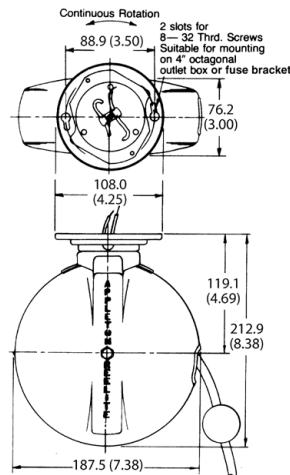

① See Lighting section, Portable Lighting.