

# 7S Continuous Swivel 7P Portable Series

## Available with or without handlamps

Furnished with 18-3 (2 wire plus safety ground) yellow SJOOW-A cord.

**NEC/CEC:**  
Listed for Ordinary Locations

### Applications

- A safe and convenient source of retractable power cord for:
  - Portable lighting
  - Power supply
  - General utility service

### Features

- 7S and 7SV Series
  - Enclosed construction.
  - Furnished with 7.6 meters (25 feet) of yellow, extra flexible, 18-3 SJOOW-A cord (2-conductor plus safety ground).
  - High quality, double copper brushes.
  - Locking ratchet holds cord at desired length.
  - Adjustable ball stop controls return limit of retractable cord.
  - Hubs in all covers have integral bushings to protect conductor insulation from damage. Hub plate openings are smooth.
  - Continuous 360° patented swiveling action without power interruption or tangling of cord.
  - 7S Series offers choice of hand-lamps available as accessories.
  - 7SV Series includes NEMA 4X (enclosed and gasketed) handlamp to accommodate up to 100 Watt lamp, 6.1 meters (20 feet) of SJOOW-A cord.
  - Models available with built-in automatic switch which activates light when cord is pulled out.
  - Convenient flush type mounting ring fits 4" octagonal outlet box or fuse bracket.
  - Accessory bracket permits wall mounting.
  - Supplied with handlamp to accommodate up to 100 Watt lamp.

### Standard Materials

- Reels: steel construction
- Cord: type SJOOW-A, yellow thermoset jacket, oil-resistant, 300 Vac rating

### Standard Finishes

- Gray hammer epoxy/polyester powder coat

### Options

- For continuous cord tension (non-locking) add suffix **-LR** to catalog number to remove the supplied cable ratchet.

### NEC/CEC Certifications and Compliances

- UL Listed: E4961
- UL Standard: 355
- CSA Listed: LR3060
- Meets OSHA requirements



7S Series




7SV Series

# 7S Continuous Swivel 7P Portable Series



## Available with or without handlamps

Furnished with 18-3 (2 wire plus safety ground) yellow SJOOW-A cord.


NEC/CEC:  
Listed for Ordinary Locations

	Description	Cord Length Meters (Feet)	Cord Size	Rating Amp/Voltage	Catalog Number
 <p><b>7SV Series</b></p>	<b>7S continuous swivel, grounded Reelite™</b> Less handlamp. Max. accessory weight: 560 grams (20 oz). Handlamps ① available. Furnished with yellow SJOOW-A cord and RE-FB4 fuse bracket assembly.	7.6 (25)	18-3 SJOOW-A	4 Amp, 125 Vac	<b>RE-7S2G</b>
	<b>7S Reelite™ with NEMA 4X, indoor use handlamp</b> Continuous swivel, grounded Reelite™ complete with RE-VHL100N (enclosed and gasketed) handlamp ① as shown. Accommodates up to 100 Watt lamp. Furnished with yellow SJOOW-A cord.	6.1 (20)	18-3 SJOOW-A	4 Amp, 125 Vac	<b>RE-7SV2G</b>
	<b>7S Reelite™ with NEMA 4X, indoor use handlamp and automatic switch</b> Continuous swivel, grounded Reelite™ complete with automatic switch (not illustrated) and RE-VHL100N (enclosed and gasketed) handlamp ①. Accommodates up to 100 Watt lamp. Furnished with yellow SJOOW-A cord.	6.1 (20)	18-3 SJOOW-A	4 Amp, 125 Vac	<b>RE-7SV2G-AS</b>

### Accessories

	Description	Catalog Number
	<b>Ball Stop</b> Yellow 2-piece split design permits installation without disconnecting handlamp or receptacle on end of cord. Made of polypropylene. Installs on SJOOW-A cord used on all Appleton portable reels.	<b>RE-PBS-1</b>
	<b>Handlamps</b> Handlamps are available as optional accessories. For ordering information refer to the <i>Lighting: Portable Lighting Section</i>	

### Dimensions in Millimeters (Inches)

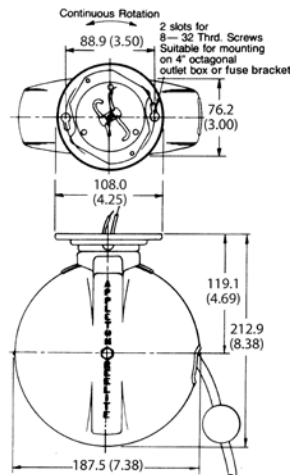

① See Lighting section, Portable Lighting.