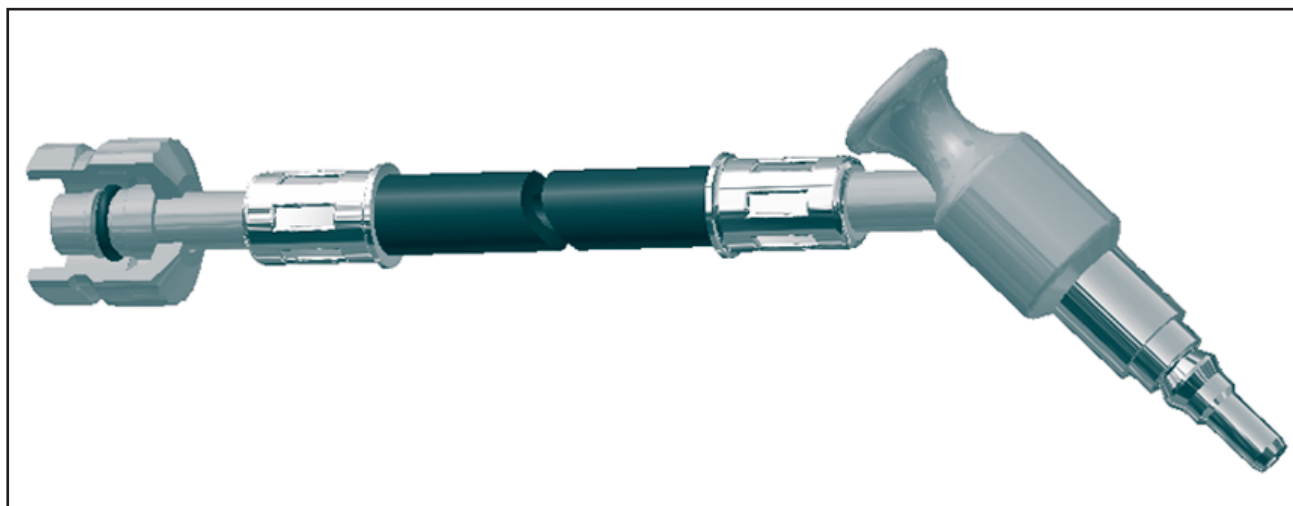


CG-Hoses SS

MEDI
CAL

Europe only

Angle plug SS 87 524 30, gascode marking and hose colour neutral, with NIST-connector, length of hose 1,5 m

O ₂	= D45690-77N150-56
Air	= D45691-77N150-56
Vac	= D45694-77N150-56
N ₂ O	= D45693-77N150-56
CO ₂	= D45692-77N150-56

Angle plug SS 87 524 30, gascode marking and hose colour acc. to ISO 32, with NIST-connector, length of hose 1,5 m

O ₂	= D45690-77I150-56
Air	= D45691-77I150-56
Vac	= D45694-77I150-56
N ₂ O	= D45693-77I150-56
CO ₂	= D45692-77I150-56

Angle plug SS 87 524 30, gascode marking hose colour neutral, with NIST-connector, length of hose 3 m

O₂ = D45690-77N300-56
Air = D45691-77N300-56
Vac = D45694-77N300-56
N₂O = D45693-77N300-56
CO₂ = D45692-77N300-56

Angle plug SS 87 524 30, gascode marking hose colour acc. to ISO 32, with NIST-connector, length of hose 3 m

O₂ = D45690-77I300-56
Air = D45691-77I300-56
Vac = D45694-77I300-56
N₂O = D45693-77I300-56
CO₂ = D45692-77I300-56

Angle plug SS 87 524 30, gascode marking hose colour neutral, with NIST-connector, length of hose 5 m

O₂ = D45690-77N500-56
Air = D45691-77N500-56
Vac = D45694-77N500-56
N₂O = D45693-77N500-56
CO₂ = D45692-77N500-56

Angle plug SS 87 524 30, gascode marking hose colour acc. to ISO 32, with NIST-connector, length of hose 5 m

O₂ = D45690-77I500-56
Air = D45691-77I500-56
Vac = D45694-77I500-56
N₂O = D45693-77I500-56
CO₂ = D45692-77I500-56

Europe only



TESCOM EUROPE GMBH & CO. KG
An der Trave 23 - 25 • D-23923 Selmsdorf • Germany
Tel: +49 (0) 3 88 23 / 31-0 • Fax: +49 (0) 3 88 23 / 31-199
eu.tescom@emerson.com

TESCOM EUROPE is a business unit of Emerson Process Management Regulator Technologies, Inc.
Trademarks are property of divisions of Emerson Process Management.
12126-09-05 Subject to technical changes

