


Product Discontinued

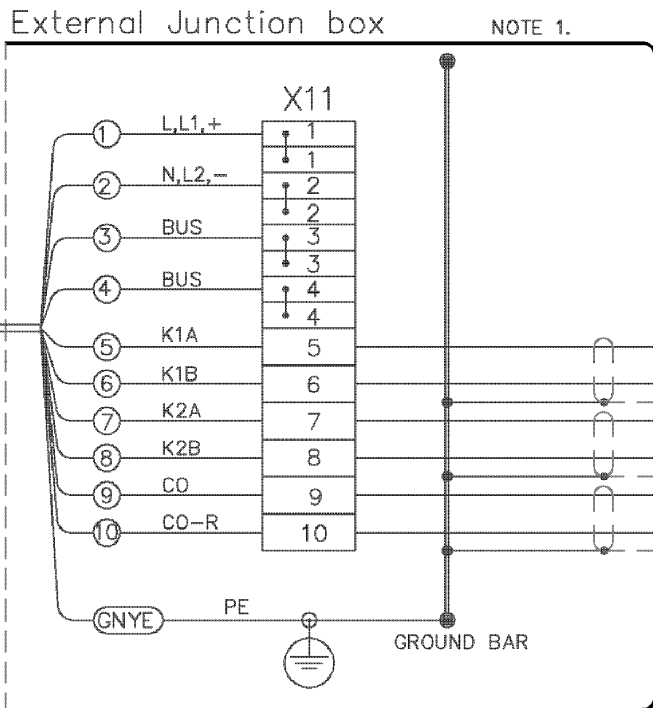


NOTE 1.

NOTE 3.

NOTE 3.

NOTE 4.

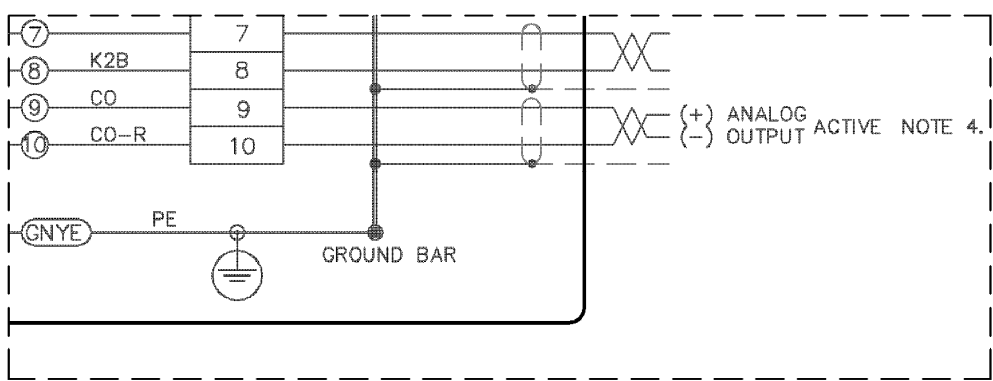

NOTE 4.

- ④ ANALOG OUTPUT ALTERNATIVE OPTIONS:
 PASSIVE OUTPUT (DEFAULT). VOLTAGE COMPLIANCE: 5-30V
 ACTIVE OUTPUT. MAX LOAD: 5000HM
 CHANGE OF CONFIGURATION (ACTIVE/PASSIVE) SEE SERVICE MANUAL.
- ③ RELAY RATING: MAX 250VAC/4A (RESISTIVE LOAD)
 THE RELAY OUTPUTS MAY BE INTERNALLY WIRED FOR NORMALLY CLOSED OR
 NORMALLY OPEN OPERATION. REFER TO THE INSTALLATION MANUAL.
- ② SHIELDED CABLE RECOMMENDED FOR VALID EMC PERFORMANCE ACC TO EN 50082-2
 SHIELD CONNECTION ONLY AT ONE END OTHERWISE A GROUND LOOP WITH
 CIRCULATING CURRENT MAY OCCUR.
- ① 2.5m FLYING LEADS FOR EXTERNAL JUNCTION BOX (CUSTOMER OR SAAB SUPPLY)
 DEPENDING ON NATIONAL CODE OF PRACTICE.

ISSUED BY GU-TKA	WEEK 0518	PRODUCT CODE REX	FILE ACAD	TITLE ELECTRICAL INSTALLATION DWG REX 2 RELAYS + AOUT W11/X11
APPROVED BY GU-HF	WEEK 0519	ORIGINAL DWG NO 9150072-883	SCALE 1:1	
ROSEMOUNT		1 ST ANGLE 	DOC. TYPE 2	DWG NO. 9150072-883
			ISSUE 2	SHEET 1/1

THE COPYRIGHT/OWNERSHIP OF THIS DOCUMENT IS AND WILL REMAIN OURS. THE DOCUMENT MUST NOT BE USED WITHOUT OUR AUTHORIZATION OR BROUGHT TO THE KNOWLEDGE OF A THIRD PARTY. CONTRAVENTION WILL BE PROSECUTED. ROSEMOUNT TANK RADAR AB, SWEDEN.