

7S CONTINUOUS SWIVEL EXTENSION CORD REELITES

Furnished with 18-3 (2 wire plus safety ground) yellow SJOOW-A cord.
Available with or without handlamps.

Applications

- A safe and convenient source of retractable power cord for portable lighting, power supply, or general utility service.

Features: 7S

- Enclosed construction, UL listed.
- Furnished with 25 ft. (7.6m) of yellow, extra flexible, 18-3 SJOOW-A cord (2-conductor plus safety ground).
- High quality, double copper brushes.
- Locking ratchet holds cord at desired length.
- Adjustable ball stop controls return limit of retractable cord.

Features: 7S Continuous Swivel Series

- Continuous 360° patented swiveling action.. without power interruption or tangling of cord.
- 7S Series offers choice of handlamps available as accessories.
- 7SV Series includes NEMA 4X (enclosed and gasketed) handlamp to accommodate up to 100W lamp, 20 ft. (6.1m) of SJOOW-A cord.
- Models available with built-in automatic switch which activates light when cord is pulled out.
- Convenient flush type mounting ring fits 4" octagonal outlet box or fuse bracket.
- Accessory bracket permits wall mounting.

Standard Materials

- Reels are steel construction.
- Cord is Type SJOOW-A, yellow thermoset jacket, oil-resistant. 300 volt rating.

Standard Finishes

- Gray hammer epoxy/polyester powder coat.

Compliances

- UL Listed†.
- NEC
- OSHA

† Reels with handlamps are UL Listed. Reels without handlamps are UL Recognized Components.



RE-7S2G

7S continuous swivel, grounded Reelite

Less handlamp. Max. accessory weight: 20 oz.(560 grams). handlamps available. * Furnished with yellow SJOOW-A cord and RE-FB4 fuse bracket.

Cord Length Feet/Meters	Cord Size	Rating Amp/Volt	Catalog Number
25' (7.6m)	18-3 SJOOW-A	4A-125V	RE-7S2G



RE-7SV2G

7S Reelite with NEMA 4X, indoor use handlamp

Continuous swivel, grounded Reelite complete with RE-VHL100N (enclosed and gasketed) handlamp as shown. *Accommodates up to 100W lamp. Furnished with yellow SJOOW-A cord.

7S Reelite with NEMA 4X, indoor use handlamp and automatic switch


Continuous swivel, grounded Reelite complete with automatic switch (not illustrated) and RE-VHL100N (enclosed and gasketed) handlamp. * Accommodates up to 100W lamp. Furnished with yellow SJOOW-A cord.

Cord Length Feet/Meters	Cord Size	Rating Amp/Volt	Catalog Number
20' (6.1m)	18-3 SJOOW-A	4A-125V	RE-7SV2G
20' (6.1m)	18-3 SJOOW-A	4A-125V	RE-7SV2G-AS


7S CONTINUOUS SWIVEL EXTENSION CORD REELITES

Furnished with 18-3 (2 wire plus safety ground) yellow SJOOW-A cord.
Available with or without handlamps.

Replacement Parts List for Type 72S / 72SG / 7SV2G Reelites Model 463

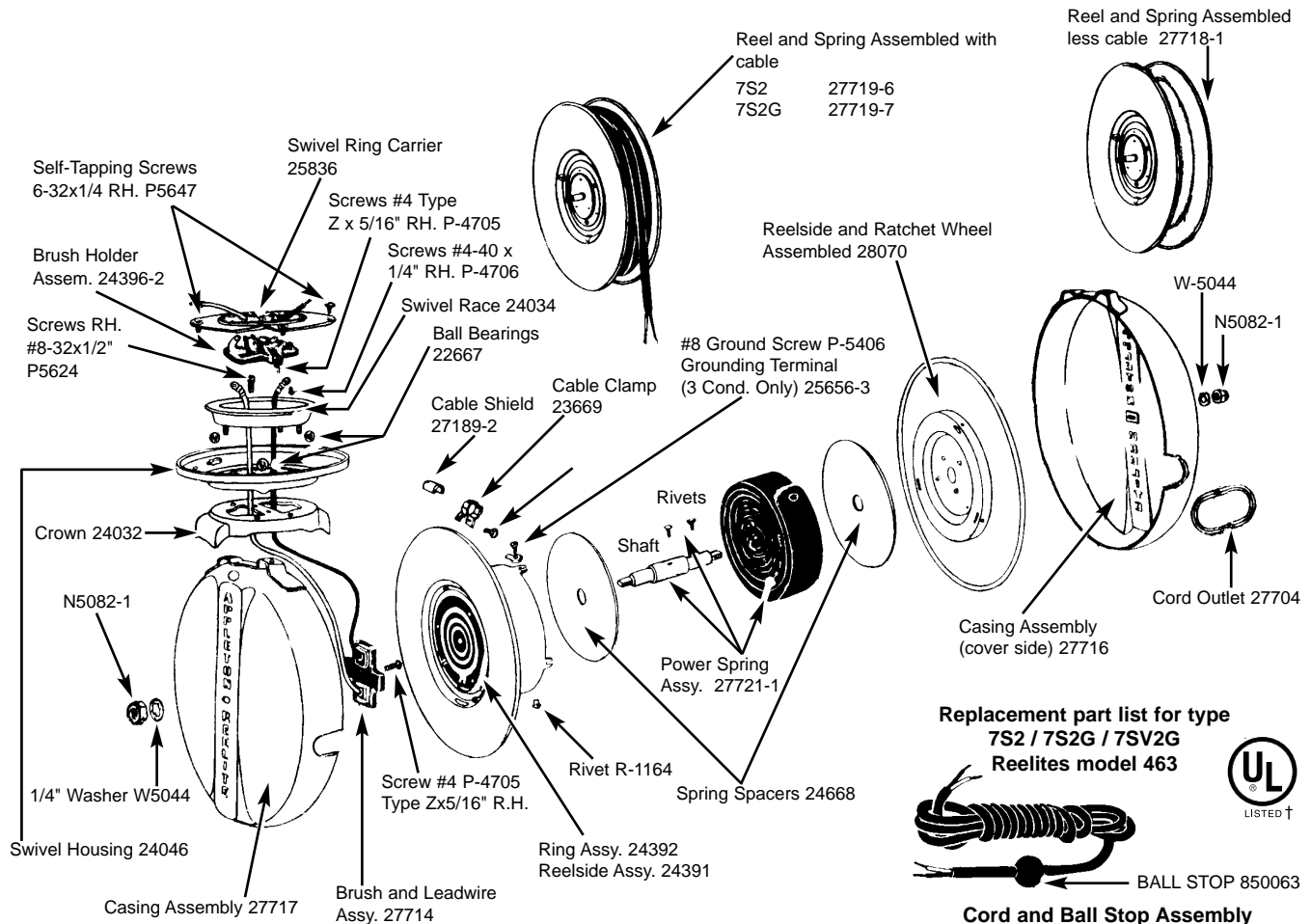

Replacement part list for type 7S2 / 7S2G / 7SV2G Reelites model 463

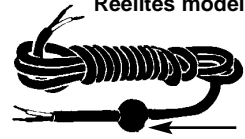

BALL STOP 850063



Cord and Ball Stop Assembly

7S2	27741-1	25'	(#16, 2 cond)
7S2G	27741-2	25'	(#18, 3 cond)
7SV2G	27741-3	20'	(#18, 3 cond)

† Reels with handlamps are UL Listed. Reels without handlamps are UL Recognized Components.

7S Series Continuous Swivel

Cat. No. RE-7S2G, RE-7SV2G, RE-7SV2G-AS

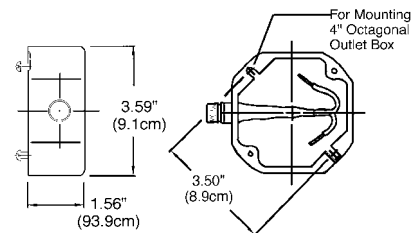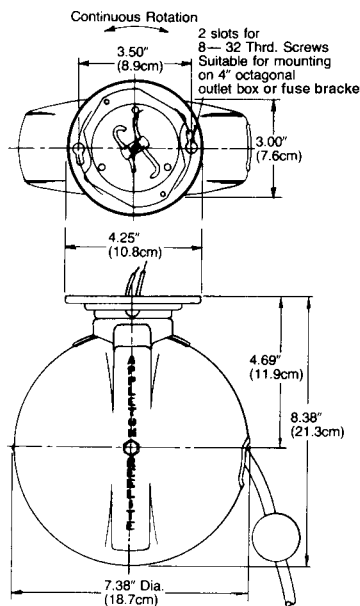

7S Continuous Swivel Series, with Handlamp



THE ORIGINAL AUTOMATIC CORD TAKE-UP REEL Operating Instructions

RATING — Collector Rings and Brushes are conservatively rated at 4 amperes, 125 volts, A.C. The rating of each Reelite is limited to the carrying capacity of the cord furnished and is listed accordingly.








SPRING TENSION — Spring Tension is pre-set to accommodate the balancing capacity listed on catalog pages. The Reel should retract both cord and accessory in any vertical application.

INSTALLATION — Mounting plate of Reelite is designed to fit neatly over any 4" octagonal outlet box, supported by the outlet box screws. The 7S Reelite is intended for vertical pendant mounting only and swivel cover should always be level to insure free swiveling and ratchet stopping action. Outlet Box should be located on flat, level surface overhead, near center of working area.

RATCHET STOP — This Reelite is equipped with three gravity type ratchet dogs allowing drum to be stopped every 120° or at approximately 6" to 8" intervals on cord. It operates on the same principle as a window shade. To set ratchet allow reel to retrieve cord slowly until ratchet falls in place and tension is set. To release ratchet, jerk cord and allow reel to retrieve cord rapidly. **DO NOT OIL OR GREASE** — Ratchet dogs must be clean and oil-free of effective operation.

CARE OF REELITE — With reasonable care in handling, your Reelite should give years of trouble-free service. Do Not Oil It - all necessary lubrication has been done at the factory. Keep the cord clean by withdrawing no more cord than needed to reach your work area. Surplus cord allowed to lie on the floor will pick up grease and dirt to be drawn into reel mechanism.

Accessories for 7S Series Extension Cord Reelites®

	Description	Max. Lamp Watts	Weight Ea. Oz./Grams	Catalog Number
	Grounded handlamp with switch and receptacle With yellow malamine phenolic handle and deluxe wire metal guard. Use with maximum 16/3 SO or SJOOW-A cord.	100W	15oz. (425g)	RE-HL5SRG
	Grounded handlamp without switch or receptacle With yellow rubber handle and vinyl coated wire metal guard. Meets OSHA requirements and NEC 511-3(f) for commercial garages, repair and storage.	100W	20oz. (567g)	RE-HL7G
	Grounded handlamp without switch or receptacle With yellow polypropylene handle and guard. Meets OSHA requirements and NEC 511-3(f) for commercial garages, repair and storage.	75W	8oz. (227g)	RE-HLG-P
	Grounded NEMA 4X handlamp without switch or receptacle Enclosed and gasketed handlamp with yellow polyester handle and teflon globe. For indoor use only. Meets OSHA requirements and NEC 511-3(f) for commercial garages, repair and storage.	100W	19oz. (539g)	RE-VHL100N
	Wall Bracket Steel wall bracket with gray hammer epoxy/polyester powder coat finish to match reels. For mounting 7S and 1500 Series Reelites on wall.			RE-WB1
	Fuse Bracket Steel adapter bracket with gray hammer epoxy/polyester powder coat finish to match reels. Brackets are furnished with reels shown, per UL requirements. Fuses are easily changed in field without disassembling reel.			RE-FB4 RE-FB5 RE-FB6 RE-FB7
	Ball Stop Yellow 2-piece split design permits installation without disconnecting handlamp or receptacle on end of cord. Made of polypropylene. Installs on SJOOW-A cord used on all Appleton portable reels. Installed as standard on all extension cord Reelites.			RE-PBS-1