



LTM Series Transmitter Quotation Request

3902 Magnolia Rd.
Pearland, Texas 77584
Phone 281-488-0788 Fax 281-488-7080

Probe Specifications: (5/8" (15.875mm) Std.)

- 316 SS Std.
 - Kynar Sleeved
 - Teflon Sleeved (if applicable)
- Alloy 20
- Hastalloy-C

Process Connections:

- 3/4" mnpt
- Flange, specify: _____

Additional Options:

- Stilling Well (recommended over 10 ft.) (minimum 3.00" I.D. or consult factory)
- Nozzle Requirements

<u>Min. S. G.</u>	<u>I.D.</u>
≥ .64	2.0" (50.8mm)
< .64	4.0" (101.6mm)

 (consult factory for more information)
- Remote Mount Electronics

Specify Cable Length _____ (25' max.)
(See Figure 2)

Area Classifications:

- FM (exp only): LTM-200D / 300
- CSA (exp): LTM-200D/250/300/350
- CSA (I/S): LTM-200D/300
- ATEX (exp only): LTM-300 / 300-FF
- IECex (exp only): LTM-300 / 300-FF

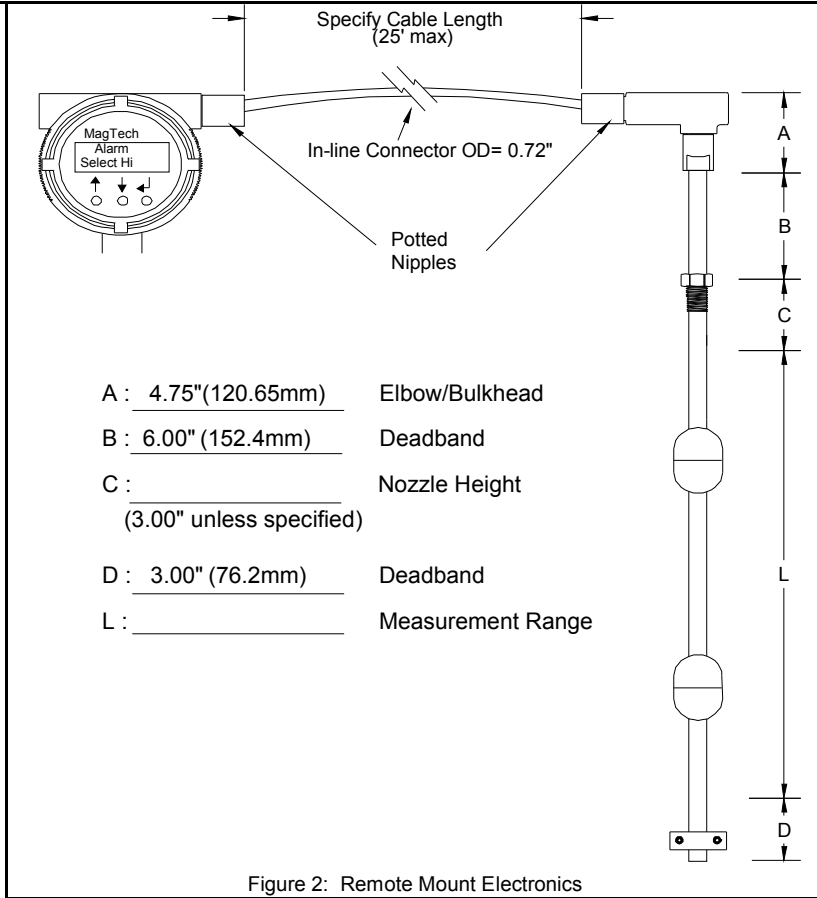


Figure 2: Remote Mount Electronics

Other Specifications: _____