


AIR SERVICE

MAINTAIN DESIRED OUTLET PRESSURE FOR CHANGES IN DOWNSTREAM DEMAND



A Series (Brass, Bronze)

- **Body Size:** 1/8 to 1/2 in. / 3.5 to 15 mm
- **Outlet Pressure Range:** 0 to 250 psig / 0 to 17.2 barg
- **Maximum Inlet Pressure:** 1100 psig / 75.8 barg
- **Maximum Capacity:** 110 SCFM
- **Temperature:** 180°F / 82°C

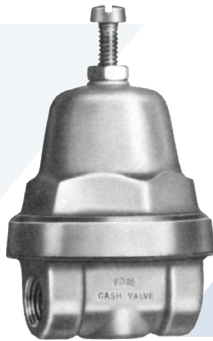

CP Series - Compressor Pilot Valves (Bronze, Stainless steel)

- **Body Size:** 1/4, 3/8 (CP2 only), 1/2 in. (CP2 only) / 8, 10 (CP2 only), 15 mm (CP2 only)
- **Outlet Pressure Range:** 0 to 600 psig / 0 to 41.4 barg
- Maintains upstream with a constant bleed on downstream



LS (Bronze)

- **Body Size:** 1/2, 3/4 in. / 15, 19 mm
- **Outlet Pressure Range:** 40 to 500 psig / 2.8 to 34.5 barg
- **Maximum Inlet Pressure:** 2400 psig / 165.5 barg
- **Maximum Capacity:** 1054 SCFM
- **Temperature:** 180°F / 82°C