


# COMPRESSOR REGULATORS

CONTROL PRESSURE IN COMPRESSOR PILOT SYSTEMS

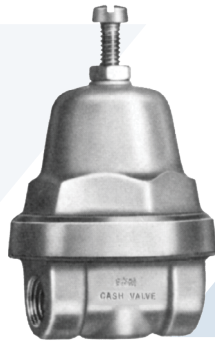

## CP Series (Bronze, Stainless steel: CP and CP2 only)

- **Body Size:** 1/4, 3/8 in.: CP2 only, 1/2 in.: CP2 only / 8, 10, 15 mm
- **Outlet Pressure Range:** 0 to 600 psig / 0 to 41.4 barg



## D-53 (Bronze)

- **Body Size:** NPS 1/2, 3/4, 1, 1 1/4, 1 1/2, 2 / DN 15, 18, 25, 32, 38, 50
- **Pressure Range:** 0 to 250 psig / 0 to 17.2 barg
- **Maximum Capacity:** 2000 SCFM / 400 GPM
- **Temperature:** 180°F / 82°C