


ISOLATION VALVES AND STRAINERS

ACCESSORIES SUPPORT CRYOGENIC CYLINDERS AND FREESTANDING TANKS



2300 (Brass)

- **Body Size:** 1/4, 3/8, 1/2 in. / 8, 10, 15 mm
- **Maximum Inlet Pressure:** 700 psig / 48.2 barg
- **Maximum Capacity:** A C_v factor of 1.3 applies to the 1/4 in. size and a C_v factor of 2.0 applies to 3/8 in. and 1/2 in. sizes
- **Temperature:** -320 to 150°F / -195 to 65.5°C

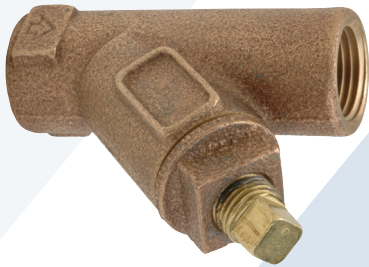

SY-70C (Bronze)

- **Body Size:** 1/2 to 2 in. / 15 to 50mm
- **Maximum Inlet Pressure:** 400 psig / 27.5 barg
- **Temperature:** -320 to 150°F / -195 to 65.5°C