


LOW TEMPERATURE CUTOFF

DEVICE TO MAINTAIN TEMPERATURE IN A DESIRED RANGE

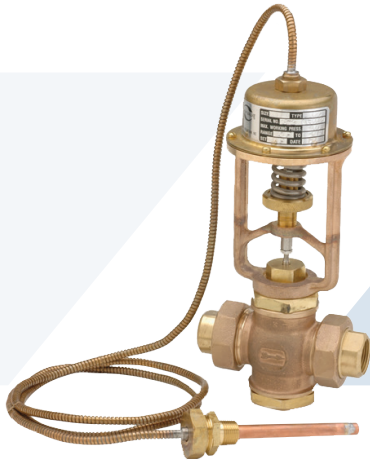

LTC (Brass, Bronze)

- **Body Size:** 1/2, 3/4, 1, 1 1/4, 1 1/2 and 2 in. / 15, 20, 25, 32, 40 and 50 mm
- **Maximum Inlet Pressure:** 400 psig / 27.6 barg
- **Maximum Capacity:** 2283 SCFM
- **Temperature:** -40 to 0°F / -40 to -18°C