

NEER™ Aluminum Set Screw Conduit Bodies and Accessories

For EMT

NEC/CEC:
Listed for Ordinary Locations

NEC/CEC:
Listed for Ordinary Locations

NEC/CEC:
Rated for Ordinary Locations

LB-SS: Aluminum Conduit Body

Applications

- Set screw type aluminum conduit bodies are used on steel EMT providing access to the interior of the raceway for wire pulling, splicing and maintenance.

Standard Material


- Diecast aluminum/epoxy powder coat

NEC/CEC Certifications and Compliances

- UL Standard: 514B
- UL Listed: E53330
- CSA Standard: C22.2 No. 18.3
- CSA Certified: 208044
- NEMA: FB-1



LB-50-SS

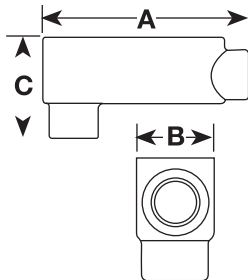

CC: Aluminum Covers

Applications

- Cover with screws for LB-SS Series conduit bodies..

Standard Material


- Diecast LM24 aluminum/epoxy powder coat

NEC/CEC Certifications and Compliances

- UL Standard: 514B
- UL Listed: E53330
- CSA Standard: C22.2 No. 18.3
- CSA Certified: 208044
- NEMA: FB-1



CC-50

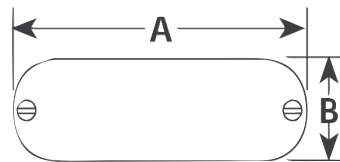

FG: Fiber Gaskets

Applications


- Cover gasket to provide sealing for LB-SS Series conduit bodies.

Standard Material

- Fiber



FG-50

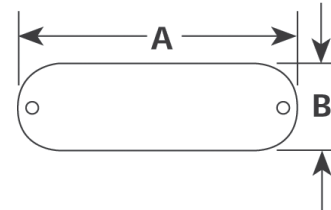

| Trade Size (Inches) | Dimensions in Millimeters (Inches) | | | Catalog Number |
|---------------------|------------------------------------|-------------|--------------|----------------|
| | A | B | C | |
| 1/2 | 111.8 (4.40) | 33.3 (1.31) | 55.9 (2.20) | LB-50-SS |
| 3/4 | 131.3 (5.17) | 38.9 (1.53) | 65.0 (2.56) | LB-75-SS |
| 1 | 147.1 (5.79) | 44.2 (1.74) | 69.6 (2.74) | LB-100-SS |
| 1-1/4 | 197.9 (7.79) | 63.2 (2.49) | 88.9 (3.50) | LB-125-SS |
| 1-1/2 | 198.4 (7.81) | 63.2 (2.49) | 92.7 (3.65) | LB-150-SS |
| 2 | 259.1 (10.20) | 78.7 (3.10) | 108.2 (4.26) | LB-200-SS |

| Trade Size (Inches) | Dimensions in Millimeters (Inches) | | Catalog Number |
|---------------------|------------------------------------|-------------|----------------|
| | A | B | |
| 1/2 | 98.3 (3.87) | 33.8 (1.33) | CC-50 |
| 3/4 | 118.1 (4.65) | 39.1 (1.54) | CC-75 |
| 1 | 136.7 (5.38) | 44.7 (1.76) | CC-100 |
| 1-1/4 and 1-1/2 | 184.2 (7.25) | 63.2 (2.49) | CC-125 |
| 2 | 240.0 (9.45) | 79.8 (3.14) | CC-200 |

| Trade Size (Inches) | Dimensions in Millimeters (Inches) | | Catalog Number |
|---------------------|------------------------------------|-------------|----------------|
| | A | B | |
| 1/2 | 98.6 (3.88) | 34.0 (1.34) | FG-50 |
| 3/4 | 118.4 (4.66) | 39.4 (1.55) | FG-75 |
| 1 | 136.9 (5.39) | 45.0 (1.77) | FG-100 |
| 1-1/4 and 1-1/2 | 184.4 (7.26) | 63.5 (2.50) | FG-125 |
| 2 | 240.3 (9.46) | 80.0 (3.15) | FG-200 |